

nVent CADDY Cat HP J-Hook Clip to BC200 Beam Clamp, 3.2–16 mm Flange

Data Solutions

NÚMERO DE CATÁLOGO

CATHPBC200



CERTIFICATIONS



CARACTERÍSTICAS

Easy installation to beam flanges

Requires no screws, rivets or special tools for assembly

J-Hooks feature bendable locking tabs that lock on to nVent CADDY Cat HP components to provide rigidity and stability

Link to J-Hooks in one of multiple color options to aid in pathway identification and organization

Customized J-Hook trees can be easily assembled with various J-Hook sizes, colors and configurations

nVent CADDY Cat HP components easily attach to any size nVent CADDY Cat HP J-Hook

CARATERÍSTICAS DO PRODUTO

Número do artigo: 181079


Material: Aço; Spring Aço

Acabamento: Electro galvanizado; nVent CADDY Armour

Espessura do flange (FT): 3.2 – 16mm

Static Load: 440N

DIAGRAMAS

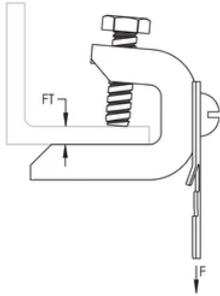

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE