


# CompacPRO Front/Rear Panel, With Hidden Fixing

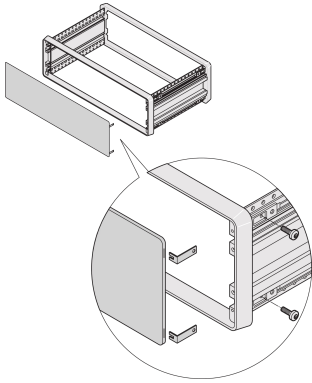

The front panel for CompacPRO Case mounts to the frame of the case. The front panel has no visible screws and can be used for front foil.

## CERTIFICATIONS



## CARACTERISTICAS

Al panel, 2.5 mm

## ESPECIFICAÇÕES

<b>Material:</b>	Aluminio
<b>Acabamento:</b>	Anodized
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel

Table 1/2

Número de catálogo	Rack Height	Altura	Rack Width	Largura	Quantidade por embalagem	Front Finish
24575-275	4U	172.9mm	84HP	452.1mm	1	Anodized
24575-075	2U	84mm	84HP	452.1mm	1	Anodized
24575-155	3U	128.4mm	63HP	345.4mm	1	Anodized

Número de catálogo	Rack Height	Altura	Rack Width	Largura	Quantidade por embalagem	Front Finish
24575-175	3U	128.4mm	84HP	452.1mm	1	Anodized
24575-455	6U	261.8mm	63HP	345.4mm	1	Anodized
24575-475	6U	261.8mm	84HP	452.1mm	1	Anodized
24575-135	3U	128.4mm	42HP	238.7mm	1	Anodized
24575-255	4U	172.9mm	63HP	345.4mm	1	Anodized
24575-035	2U	84mm	42HP	238.7mm	1	Anodized
24575-235	4U	172.9mm	42HP	238.7mm	1	Anodized
24575-115	3U	128.4mm	28HP	167.5mm	1	Anodized

Table 2/2

Número de catálogo	Rear Finish	Treated Edges	Profundidade
24575-275	Anodized	Não	2.5mm
24575-075	Anodized	Não	2.5mm
24575-155	Anodized	Não	2.5mm
24575-175	Anodized	Não	2.5mm
24575-455	Anodized	Não	2.5mm
24575-475	Anodized	Não	2.5mm
24575-135	Anodized	Não	2.5mm
24575-255	Anodized	Não	2.5mm
24575-035	Anodized	Não	2.5mm
24575-235	Anodized	Não	2.5mm
24575-115	Anodized	Não	2.5mm

## AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



O nosso forte portefólio de marcas:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**