


CPCI System for Pluggable PSU, Horizontal, 3 U, 6 Slot

NÚMERO DE CATÁLOGO

24579-080

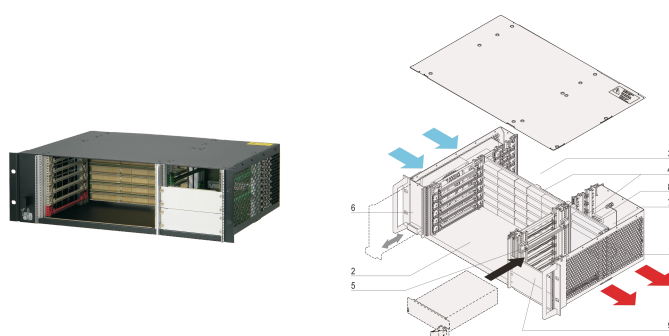

3 U CompactPCI System with horizontal Card Cage for six 6 U Boards, six RTM Boards and one CompactPCI 3 U Pluggable Power Supply. Option to assemble up to three pluggable Power Supplies.

CERTIFICATIONS



CARACTERÍSTICAS

In accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; backplane in accordance with PICMG 2.0 rev. 3.0

System with horizontal card cage. Board format Front: 6 U, 160 mm deep; Rear I/O: 6 U, 80 mm deep

Backplane (signal and power backplane in one unit) 6 slot, 6 U, 64 bit, System slot left, Power connector (2 x P 47)

Heat dissipation by hot-swap fan unit (airflow left to right)

Prepared for the assembly of a 19" CompactPCI power supply (3 U, 8 HP)

CARATERÍSTICAS DO PRODUTO

Product Type: System

Number of Slots: 6

Tipo: 19" Rack Mount

Backplane Type: 6 U CompactPCI

Data Transfer: 64-bit PCI Bus

Power per Slot: 40W

Tensão de entrada AC: 100 – 240V

Airflow Direction: Left to Right

Rack Height: 3U

Power Supply Type: (1) Pluggable PSU

Power Supply Included: Não

Rear I/O: Sim

Em conformidade com: PICMG 2.0 R3.0

Profundidade: 275mm

Altura: 132.5mm

Largura: 449mm

Net Weight: 8.57kg

Quantidade por embalagem: 1

DETALHES ADICIONAIS DO PRODUTO

Modified systems available on request.

48 VDC version on request.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE