

BD Two Pole Distribution Block, 40 A

Data Solutions



CERTIFICATIONS



CARACTERÍSTICAS

Minimum space for maximum power

Protection cover and insulating screens are transparent

Insulating screen between each row

Easy and safe connections

Easily clips onto DIN rail or mounts to panel with screws

RoHS compliant

Conforms to EN 45545 obtaining an HL3 classification for chapter R23 and HL2 classification for chapter R22

Halogen free

ESPECIFICAÇÕES

Table 1/2

Número de catálogo

BD-40A

Número do artigo	563720
Max Current Rating, IEC	40A
Short Term Withstand Current (Icw) 1s	4.5kA
Peak Short Circuit Current (Ipk)	22kA
Max Working Voltage, IEC (Ui)	500
Line Side Number of Connections	2
Line Side Compact Stranded Wire Size	6 - 16 mm ²
Line Side Stranded Wire Size - Ferrule	4 – 10mm ²
Load Side Number of Connections	15
Load Side Compact Stranded Wire Size	(15) 1,5 - 4 mm ²
Load Side Stranded Wire Size - Ferrule	(15) 0,75 – 4 mm ²
Profundidade (D)	50mm
Altura (H)	50mm
Largura (W)	130mm
Peso unitário	0.22kg
Flammability Rating	UL® 94V-0


Table 2/2

Número de catálogo	BD-40A
Em conformidade com	IEC® 60947-7-1

DETALHES ADICIONAIS DO PRODUTO

Line side and load side number of connections are per pole.

DIAGRAMAS

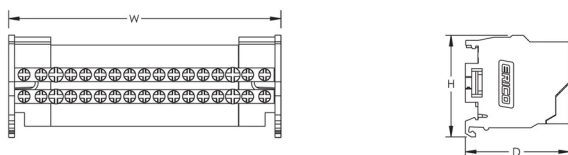

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE