


# MTCA.0 System for 2 Single Full-Size AMC Modules, 1 HE

NÚMERO DE CATÁLOGO

11850-023

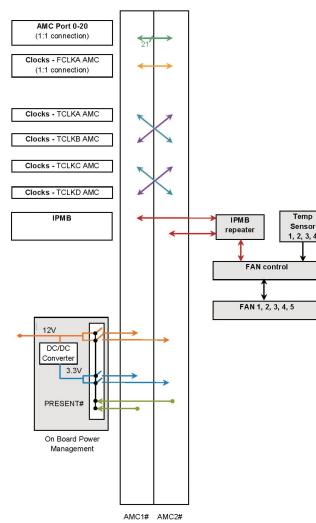

The System is designed for 2 AMC modules. The integrated Power Supply and Power switches on the backplane enable the Payload Power to the AMC Modules without the need for a separate MCH.

## CERTIFICATIONS



## CARACTERÍSTICAS

---

Small, compact case to hold 2 single full-size AdvancedMC modules With an optional 2 HP filler module, 2 single mid-size modules can also be fitted

Direct connection of all ports between both AdvancedMC slots (see backplane topology); data transfer rates up to 10 Gbps per port

90 - 264 VAC wide range input on rear of case, 150 W power supply in rear section of enclosure

12 VDC voltage is activated by the AdvancedMC module presence signal

150 W cooling capacity at an ambient temperature of 55 °C, airflow from right to left, temperature-regulated fans

Fan unit and fan filter are easy to service or replace

The enclosure is stackable and prepared for plate mounting

## CARATERÍSTICAS DO PRODUTO

---

Product Type: System

Number of Slots: 2

Tipo: Pico System

Backplane Type: All Ports Point to Point Connected

Data Transfer: 40 GbE; PCIe Gen3

Power per Slot: 60W

Tensão de entrada AC: 100 – 240V

Airflow Direction: Right to Left

Rack Height: 1U

Power Supply Type: Open Frame

Power Supply Included: Sim

Rear I/O: Não

Em conformidade com: PICMG MTCA.0 R2.0

Profundidade: 302mm

Quantidade por embalagem: 1

## DETALHES ADICIONAIS DO PRODUTO

---

Modified systems available on request.

Completely assembled, wired and tested.

## AVISO

---

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



O nosso forte portefólio de marcas:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**