


# AirBender, Card Guide Insert, 70P Blockage, 4HP, 160mm, 10 Pieces Kit

## NÚMERO DE CATÁLOGO

**24563-040**

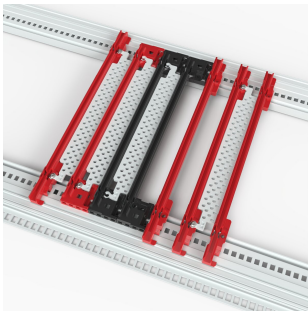

The nVent SCHROFF AirBender Inlay enhances cooling efficiency by up to 85% per slot by balancing airflow in mixed impedance environments. It is easy to install, reduces fan noise, and improves overall system performance.

## CARACTERÍSTICAS

AirBender card guide inserts enhance cooling efficiency in electronic systems by up to 85% per 4HP slot by balancing airflow in environments with mixed air impedances

70% blockage: The AirBender introduces additional air impedance in slots with less critical components, redirecting airflow to more vulnerable zones and ensuring better cooling outcomes for all cards

Easy installation: Simply clip the AirBender into nVent SCHROFF plastic card guides and optionally secure it with a screw

Favors reduced noise development from the fans by maintaining them at an efficient operating point

Air bender and CassettePRO cannot be used together in the same slot.

## CARATERÍSTICAS DO PRODUTO

Product Type: Air Baffle

Família de produtos: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac

Works With: Subracks; Cases; Systems

Rack Width: 4HP

Profundidade: 160mm

Material: Policarbonato

Quantidade por embalagem: 10

Cor: Grey

Em conformidade com: EN 45545-2; UL® 94V-0

## DETALHES ADICIONAIS DO PRODUTO

---

AirBenders with different blockage levels available on request.

## AVISO

---

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



O nosso forte portfólio de marcas:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**