


# Adjustable Fixing Bracket

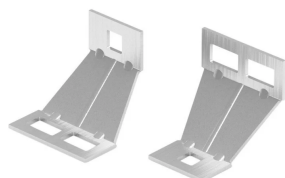

## CERTIFICATIONS



## CARACTERISTICI

Secures SPEEDWAY Cable Ladder to structural elements for horizontal and vertical runs

Installs quickly and easily with included hardware

Low profile allows for installations in tight spaces

## SPECIFICAȚII



Table 1/2

| Număr de catalog | Article Number | Material | Finish             | A     | B     | C     |
|------------------|----------------|----------|--------------------|-------|-------|-------|
| CLSWAFBGA        | 842050         | Oțel     | Hot-Dip Galvanized | 60 mm | 40 mm | 58 mm |

Table 2/2

| Număr de catalog | Article Number | D      |
|------------------|----------------|--------|
| CLSWAFBGA        | 842050         | 2.5 mm |

## DIAGRAMS

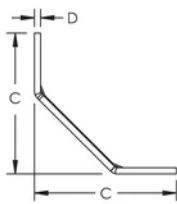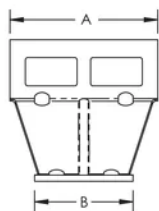

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

