

# Heavy Duty Pipe Clamp per DIN 3567, Steel, HD, 60.3mm OD, 2" Pipe, 50 DN

## NUMĂR DE CATALOG

---

### DIN060HD



## CARACTERISTICI

---

For high static requirements in industrial construction

Suitable for fix point applications

Can be welded onto T-beam to form a sliding element

## ATRIBUTE PRODUS

---

Article Number: 400208

Material: Oțel

Finish: Hot-Dip Galvanized

Outer Diameter (OD): 60.3 mm

Pipe Size: 2" Min

NB/DN: 50


Hole Size (HS): 14 mm

Width (W): 40 mm

Thickness (T): 6 mm

A: 108 mm

## DIAGRAMS

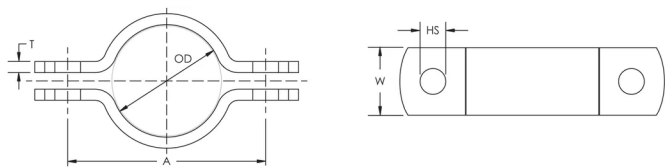

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

