

# nVent CADDY Macrofix Insulated M8/M10, Stainless Steel, 68–78 mm OD, 2 1/2" Pipe, 65 DN

## NUMĂR DE CATALOG

**MFD078S6**



## CERTIFICATIONS



## CARACTERISTICI

Return-lip on the hanger prevents the rubber from detaching, eliminating rework during installation

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## ATRIBUTE PRODUS

Article Number: 586310

Material: EPDM-SBR Rubber;Stainless Steel 316L (EN 1.4404)

Finish: Electropolished

Color: Black

Temperature: -50 to 110 °C

Outer Diameter (OD): 68 - 78 mm

Pipe Size: 2 1/2"

NB/DN: 65

Rod Size (RS): M8;M10

Width (W): 23 mm

Thickness (T): 1.5 mm

Screw Diameter (Sc): 6


Screw Length (L): 32mm

Static Load: 700N

## DETALII SUPLIMENTARE DESPRE PRODUS

Lining is EPDM rubber.

## DIAGRAMS

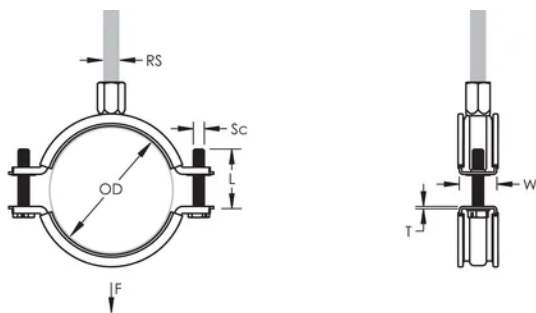

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

