

# PX NI HD Pipe Clamp w/Ext. Thread, Steel, EG, 74–79 mm OD, 1/2" Thread, 31 mm

## NUMĂR DE CATALOG

### PXN079EG



## CARACTERISTICI

Includes male/female combination nut

Heavy duty

## ATRIBUTE PRODUS

Article Number: 577160

Nut Included: Yes

Material: Oțel

Finish: Electrogalvanized

Outer Diameter (OD): 74 - 79 mm

Pipe Size: 2 1/2"

NB/DN: 65

Rod Size (RS): M10

Gewinde (G): 1/2"

Width (W): 31 mm


Thickness (T): 2.5 mm

Screw Diameter (Sc): 6

Screw Length (L): 25mm

Static Load: 2500N

## DIAGRAMS

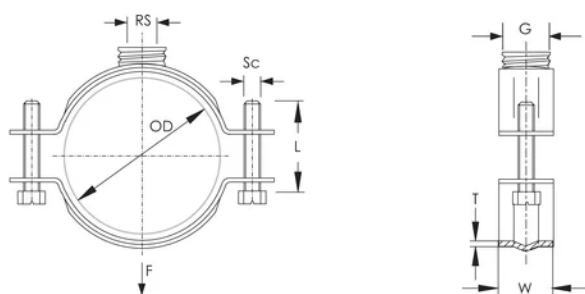

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

