

Vertical Adjustable Coupler



CERTIFICATIONS



CARACTERISTICI

Provides high-strength joint with SPEEDWAY Cable Ladder profile

Integral hinge allows simple vertical cable ladder joint adjustments

Installs quickly and easily with included hardware

Multiple slots allow for field adjustments

SPECIFICAȚII


Table 1/2

| Număr de catalog | Article Number | Material | Finish | Angle (a) | A | B |
|------------------|----------------|----------|--------------------|-----------|--------|-------|
| CLSW4VACGA | 842030 | Oțel | Hot-Dip Galvanized | 0 - 90 ° | 150 mm | 62 mm |

Table 2/2

| Număr de catalog | Article Number | C |
|------------------|----------------|------|
| CLSW4VACGA | 842030 | 2 mm |

DIAGRAMS

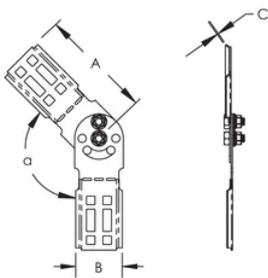

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

