

# 19" Front Panel

## Data Solutions

Front panels made of Aluminum.



### CERTIFICATIONS



### CARACTERISTICI

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

### SPECIFICAȚII

- Rack Width:** 95HP
- Material:** Aluminiu
- Accessory Type:** Front panel
- Product Type:** Front Panel

Table 1/3

| Număr de catalog | Rack Height | Depth (D) | Mounting       | Finish         | Front Finish | Package Quantity |
|------------------|-------------|-----------|----------------|----------------|--------------|------------------|
| 30118-299        | 1U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30118-948        | 1U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30219-098        | 1U          | 3mm       | Screw-on Front | Anodized       | Anodized     | 1                |

| Număr de catalog | Rack Height | Depth (D) | Mounting       | Finish         | Front Finish | Package Quantity |
|------------------|-------------|-----------|----------------|----------------|--------------|------------------|
| 40304-074        | 1U          | 4mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 30219-137        | 7U          | 3mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 30118-956        | 9U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30219-113        | 6U          | 3mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 30219-110        | 5U          | 3mm       | Screw-on Front | Vopsit Pulbere | Anodized     | 1                |
| 30219-107        | 4U          | 3mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 30118-949        | 2U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30118-950        | 3U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30219-104        | 3U          | 3mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 30118-951        | 4U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30118-303        | 4U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30219-101        | 2U          | 3mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 30118-952        | 5U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30118-302        | 3U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30118-953        | 6U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30118-954        | 7U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30118-957        | 10U         | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30118-955        | 8U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30118-301        | 2U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 40304-083        | 10U         | 4mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 40304-082        | 9U          | 4mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 40304-081        | 8U          | 4mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 40304-080        | 7U          | 4mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 40304-079        | 6U          | 4mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 40304-078        | 5U          | 4mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 40304-077        | 4U          | 4mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 40304-076        | 3U          | 4mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 30118-305        | 6U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 40304-075        | 2U          | 4mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 30118-306        | 7U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30118-307        | 8U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30219-144        | 10U         | 3mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 30118-304        | 5U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30219-143        | 9U          | 3mm       | Screw-on Front | Anodized       | Anodized     | 1                |

| Număr de catalog | Rack Height | Depth (D) | Mounting       | Finish         | Front Finish | Package Quantity |
|------------------|-------------|-----------|----------------|----------------|--------------|------------------|
| 30118-308        | 9U          | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |
| 30219-138        | 8U          | 3mm       | Screw-on Front | Anodized       | Anodized     | 1                |
| 30118-309        | 10U         | 3mm       | Screw-on Front | Vopsit Pulbere | Painted      | 1                |

Table 2/3

| Număr de catalog | Rear Finish | Treated Edges | Color Code | EMC Shielding | Height (H) | Type            |
|------------------|-------------|---------------|------------|---------------|------------|-----------------|
| 30118-299        | Painted     |               | RAL 7035   | No            | 43.6mm     | 19" Front Panel |
| 30118-948        | Painted     |               | RAL 7021   | No            | 43.6mm     | 19" Front Panel |
| 30219-098        | Anodized    | No            |            | No            | 43.6mm     | 19" Front Panel |
| 40304-074        | Anodized    | Yes           |            | No            | 43.6mm     | 19" Front Panel |
| 30219-137        | Anodized    | No            |            | No            | 310.3mm    | 19" Front Panel |
| 30118-956        | Painted     |               | RAL 7021   | No            | 399.2mm    | 19" Front Panel |
| 30219-113        | Anodized    | No            |            | No            | 265.9mm    | 19" Front Panel |
| 30219-110        | Anodized    | No            |            | No            | 221.4mm    | 19" Front Panel |
| 30219-107        | Anodized    | No            |            | No            | 177mm      | 19" Front Panel |
| 30118-949        | Painted     |               | RAL 7021   | No            | 88.1mm     | 19" Front Panel |
| 30118-950        | Painted     |               | RAL 7021   | No            | 132.5mm    | 19" Front Panel |
| 30219-104        | Anodized    | No            |            | No            | 132.5mm    | 19" Front Panel |
| 30118-951        | Painted     |               | RAL 7021   | No            | 177mm      | 19" Front Panel |
| 30118-303        | Painted     |               | RAL 7035   | No            | 177mm      | 19" Front Panel |
| 30219-101        | Anodized    | No            |            | No            | 88.1mm     | 19" Front Panel |
| 30118-952        | Painted     |               | RAL 7021   | No            | 221.4mm    | 19" Front Panel |
| 30118-302        | Painted     |               | RAL 7035   | No            | 132.5mm    | 19" Front Panel |
| 30118-953        | Painted     |               | RAL 7021   | No            | 265.9mm    | 19" Front Panel |
| 30118-954        | Painted     |               | RAL 7021   | No            | 310.3mm    | 19" Front Panel |
| 30118-957        | Painted     |               | RAL 7021   | No            | 443.7mm    | 19" Front Panel |
| 30118-955        | Painted     |               | RAL 7021   | No            | 354.8mm    | 19" Front Panel |
| 30118-301        | Painted     |               | RAL 7035   | No            | 88.1mm     | 19" Front Panel |
| 40304-083        | Anodized    | Yes           |            | No            | 443.7mm    | 19" Front Panel |
| 40304-082        | Anodized    | Yes           |            | No            | 399.2mm    | 19" Front Panel |
| 40304-081        | Anodized    | Yes           |            | No            | 354.8mm    | 19" Front Panel |
| 40304-080        | Anodized    | Yes           |            | No            | 310.3mm    | 19" Front Panel |
| 40304-079        | Anodized    | Yes           |            | No            | 265.9mm    | 19" Front Panel |
| 40304-078        | Anodized    | Yes           |            | No            | 221.4mm    | 19" Front Panel |

| Număr de catalog | Rear Finish | Treated Edges | Color Code | EMC Shielding | Height (H) | Type            |
|------------------|-------------|---------------|------------|---------------|------------|-----------------|
| 40304-077        | Anodized    | Yes           |            | No            | 177mm      | 19" Front Panel |
| 40304-076        | Anodized    | Yes           |            | No            | 132.5mm    | 19" Front Panel |
| 30118-305        | Painted     |               | RAL 7035   | No            | 265.9mm    | 19" Front Panel |
| 40304-075        | Anodized    | Yes           |            | No            | 88.1mm     | 19" Front Panel |
| 30118-306        | Painted     |               | RAL 7035   | No            | 310.3mm    | 19" Front Panel |
| 30118-307        | Painted     |               | RAL 7035   | No            | 354.8mm    | 19" Front Panel |
| 30219-144        | Anodized    | No            |            | No            | 443.7mm    | 19" Front Panel |
| 30118-304        | Painted     |               | RAL 7035   | No            | 221.4mm    | 19" Front Panel |
| 30219-143        | Anodized    | No            |            | No            | 399.2mm    | 19" Front Panel |
| 30118-308        | Painted     |               | RAL 7035   | No            | 399.2mm    | 19" Front Panel |
| 30219-138        | Anodized    | No            |            | No            | 354.8mm    | 19" Front Panel |
| 30118-309        | Painted     |               | RAL 7035   | No            | 443.7mm    | 19" Front Panel |

Table 3/3


| Număr de catalog | Width (W) |
|------------------|-----------|
| 30118-299        | 483mm     |
| 30118-948        | 483mm     |
| 30219-098        | 483mm     |
| 40304-074        | 483mm     |
| 30219-137        | 483mm     |
| 30118-956        | 483mm     |
| 30219-113        | 483mm     |
| 30219-110        | 483mm     |
| 30219-107        | 483mm     |
| 30118-949        | 483mm     |
| 30118-950        | 483mm     |
| 30219-104        | 483mm     |
| 30118-951        | 483mm     |
| 30118-303        | 483mm     |
| 30219-101        | 483mm     |
| 30118-952        | 483mm     |
| 30118-302        | 483mm     |
| 30118-953        | 483mm     |
| 30118-954        | 483mm     |
| 30118-957        | 483mm     |

| Număr de catalog | Width (W) |
|------------------|-----------|
| 30118-955        | 483mm     |
| 30118-301        | 483mm     |
| 40304-083        | 483mm     |
| 40304-082        | 483mm     |
| 40304-081        | 483mm     |
| 40304-080        | 483mm     |
| 40304-079        | 483mm     |
| 40304-078        | 483mm     |
| 40304-077        | 483mm     |
| 40304-076        | 483mm     |
| 30118-305        | 483mm     |
| 40304-075        | 483mm     |
| 30118-306        | 483mm     |
| 30118-307        | 483mm     |
| 30219-144        | 483mm     |
| 30118-304        | 483mm     |
| 30219-143        | 483mm     |
| 30118-308        | 483mm     |
| 30219-138        | 483mm     |
| 30118-309        | 483mm     |

## DETALII SUPLIMENTARE DESPRE PRODUS

Please order 19" assembly kit separately.

## DIAGRAMS

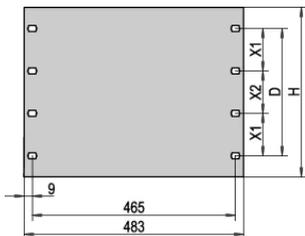

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și

avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**