


Joint Bond T6 Complete Welder Pair, Signal, Head Free Bond Terminal Style, 3/16" Bondstrand

Data Solutions

NUMĂR DE CATALOG

SBHFT6A

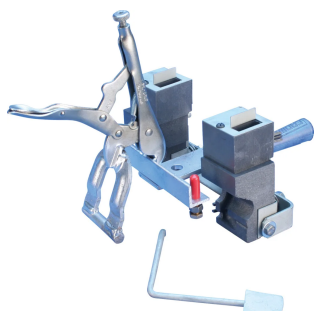

CARACTERISTICI

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail, across the joint

Connection is made within the confines of the splice bar

Includes mold cleaner

ATTRIBUTE PRODUS

Material: Oțel; Graphite; Thermoplastic

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: Head Free

Conductor Size: 3/16" Bondstrand

Conductor Outer Diameter, Nominal: 4.76mm

Bond Length: 165.1mm

Welder Style: T6

Mold Only: No

Replacement Mold: SBS925

Welding Material: SB25 x 2, Sold Separately

Frame: SBS925F, Sold Separately

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE