


Four Pole Distrib. Block with Threaded Bars, 400 A

Data Solutions

NUMĂR DE CATALOG

TR-400A

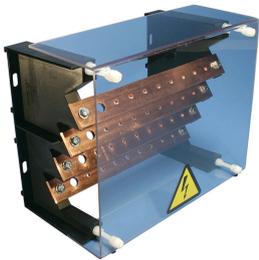

CERTIFICATIONS



CARACTERISTICI

Easily fixes onto DIN rail or mounts with screws

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

ATRIBUTE PRODUS

Article Number: 562010

Material: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 1000

Peak Short Circuit Current (Ipk): 34kA

Short Term Withstand Current (Icw) 1s: 28kA

Line Side Number of Connections: 1

Load Side Number of Connections: 8

Hole Size (HS): 12mm

Thread Size (TS): M6

Depth (D): 140mm

Height (H): 240mm

Width (W): 300mm

Unit Weight: 2.83kg


Flammability Rating: UL® 94V-0

Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

DETALII SUPLIMENTARE DESPRE PRODUS

Line side and load side number of connections are per pole.

DIAGRAMS

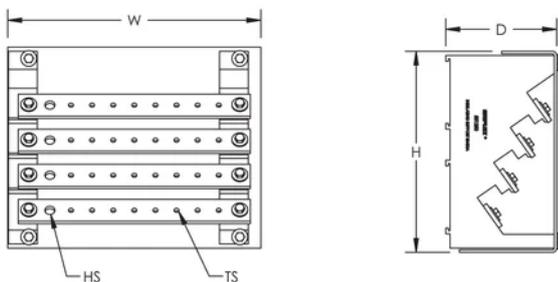

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE