


# Basic PDU, EB0332, 230 VAC, 1-PH, 63 A

## Data Solutions

### NUMĂR DE CATALOG

---

## EB0332

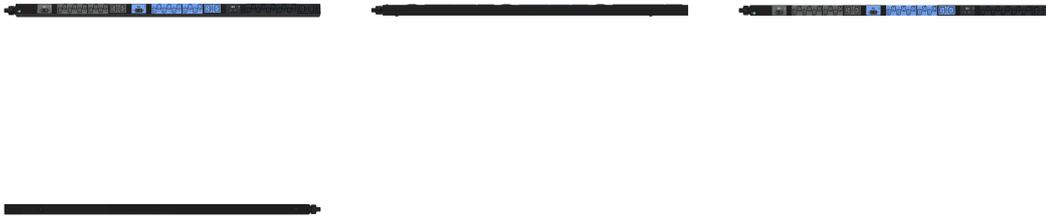

Modular, compact PDU. Ultra-Low Profile Design

### CARACTERISTICI

---

Enlogic Basic Power Distribution Units enable power in Cabinets as well as Open Frame Racks and Wall-Mount enclosures

Input Voltage 230 VAC, 1-phase

C13 and C19 outlets

1RU aluminum profile

Adjustable Toolless Mounting

### ATRIBUTE PRODUS

---

Product Family: Enlogic

Type: Basic PDU

Product Type: Socket Strip

Socket Type: (30) C13; (6) C19

Socket Quantity: 36

Color: Black

Circuit Breaker: 16 A, 1-pole, Hy-Mag

Switched Outlets: No

Circuit Breaker Quantity: 3

Input Cable Location: Top Feed

Input Voltage: 200 – 240V

Phase: 1 PH

Interrupt Rating: 5kAIC

Max Power Input: 11.0 kVA

Output Voltage: 200 – 240VAC

Amperage (Derated Amperage): 63 A

Plug Type: IEC 60309 363P6 (IP44)

Rack Units: 0U

Removable Input Cable: No

Metering Type: None

Package Quantity: 1

Gross Weight: 10kg

Input Cable Length: 3m

## DETALII SUPLIMENTARE DESPRE PRODUS

---

Please order bracket for vertical mounting separately.

## AVERTIZARE

---

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**