


Basic PDU, EB0850, 400 VAC, 3-PH, 32 A

Data Solutions

NUMĂR DE CATALOG

EB0850

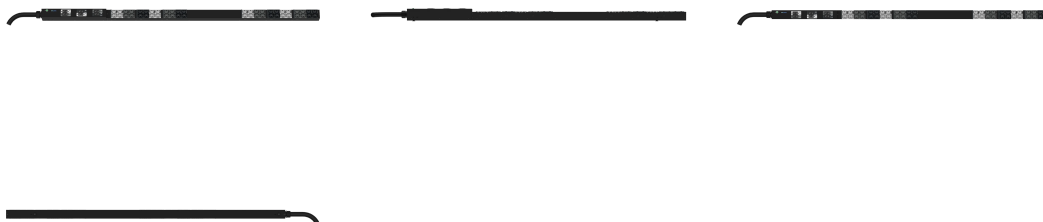

Modular, compact PDU. Ultra-Low Profile Design

CARACTERISTICI

Enlogic Basic Power Distribution Units enable power in Cabinets as well as Open Frame Racks and Wall-Mount enclosures

Input Voltage 400 VAC, 3-phase

C13 and C19 outlets

1RU aluminum profile

Adjustable Toolless Mounting

ATTRIBUTE PRODUS

Product Family: Enlogic

Type: Basic PDU

Product Type: Socket Strip

Socket Type: (24) C13/C15; (24) C13/C15/C19/C21

Socket Quantity: 48

Color: Black

Circuit Breaker: 16 A, 1-pole, Hy-Mag

Switched Outlets: No

Circuit Breaker Quantity: 6

Power Rating: 17.3 kVA North America; 22.1 kVA International

Input Cable Length: 1.8m

Input Cable Location: Top Feed

Input Voltage: 380 – 415V

Phase: 3 PH

Nominal Voltage: 415V

Max Power Input: 17.3 / 22.1 kVA

On/Off Switch Included: No

Amperage (Derated Amperage): 30 A (24 A) North America; 32 A International

Output Voltage: 208 – 230VAC

Rack Units: 0U

Plug Type: IEC 60309 530P6/532P6

Metering Type: None

Removable Input Cable: No

Material: Oțel

Finish: Vopsit Pulbere

Height: 1780mm

Width: 56mm

Depth: 55mm

Weight: 10kg

Package Quantity: 1

DETALII SUPLIMENTARE DESPRE PRODUS

Please order bracket for vertical mounting separately.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE