


# MI PDU, 2U, 100A(80A), 208V, 3P Delta, 9 CB, (18)4-in-1

## Data Solutions

### NUMĂR DE CATALOG

### EN1964

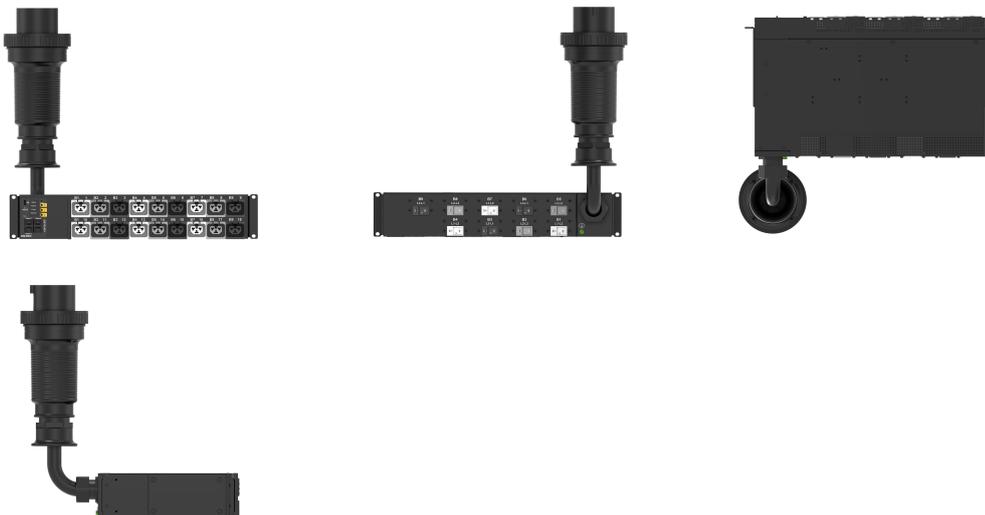

The Advantage Series Input Metered PDU family offers energy metering with advanced power and environmental monitoring options. Comprehensive monitoring at both the input phase and circuit breaker levels offers advanced alerts of potential overloads. Billing-grade metering provides accurate power consumption data for energy use optimization. The hot-swappable network management controller features Gigabit and redundant ethernet communication with advanced support for external environmental sensors and rack security access solutions.

### ATRIBUTE PRODUS

Product Family: Enlogic

Product Type: Socket Strip

Socket Type: (18) C13/C15/C19/C21

Color: Black

Switched Outlets: No

Circuit Breaker: 20 A

Length: 87mm

Power Rating: 28.8 kVA

Circuit Breaker Quantity: 9

Input Voltage: 208V

Phase: 3 PH Delta

Number of Poles: 2

Output Voltage: 208VAC

Nominal Voltage: 208V

Plug Type: IEC 60309 4100P9W

Removable Input Cable: No

Amperage (Derated Amperage): 100 A (80 A)

Finish: Vopsit Pulbere

Rack Units: 2U

Material: Oțel

Type: Intelligent PDU

Height: 87mm

Width: 444mm

Depth: 269mm

Weight: 11kg

Package Quantity: 1

Input Cable Length: 1.8m

Interrupt Rating: 10kAIC

## DETALII SUPLIMENTARE DESPRE PRODUS

---

43 mm L x 444 mm W x 269 mm D, (269 mm D at CB)

## AVERTIZARE

---

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**