

Solid Copper Ground Rod, Sectional Internal Thread



CARACTERISTICI

Solid copper sectional ground rod with internal threading

SPECIFICAȚII

Tensile Strength: 50 MPa

Material: Copper


Table 1/1

Număr de catalog	Article Number	Ground Rod Diameter, Actual (Ø)	Thread Size (TS)	Length (L)	Unit Weight
SCR15	710070	15 mm	M10	1.2m	1.64 kg
SCR20	710080	20 mm	M10	1.2m	3.34 kg

DETALII SUPLIMENTARE DESPRE PRODUS

Due to the inherent softness of the copper material, special consideration should be given when driving this product into the soil.

DIAGRAMS

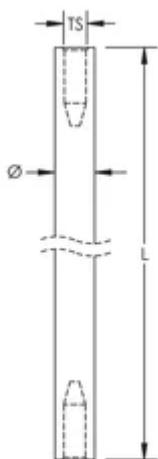

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE