

19" Front Panel, Vented

Vented front panels allows heat dissipation through holes.



CERTIFICATIONS



CARACTERISTICI

Vented front panels (Aluminum) allows heat dissipation

SPECIFICAȚII

- Rack Width:** 95HP
- Material:** Aluminiu
- Accessory Type:** Front panel
- Product Type:** Front Panel

Table 1/2

Număr de catalog	Rack Height	Finish	Mounting	Package Quantity	Front Finish	Rear Finish
30118-962	1U	Vopsit Pulbere	Screw-on Front	1	Painted	Painted
30702-047	1U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-056	1U	Vopsit Pulbere	Screw-on Front	1	Painted	Painted
30702-044	1U	Anodized	Screw-on Front	1	Raw	Conductive
30118-963	2U	Anodized	Screw-on Front	1	Painted	Painted
30702-048	2U	Anodized	Screw-on Front	1	Anodized	Anodized

Număr de catalog	Rack Height	Finish	Mounting	Package Quantity	Front Finish	Rear Finish
30702-057	2U	Vopsit Pulbere	Screw-on Front	1	Painted	Painted
30118-964	3U	Vopsit Pulbere	Screw-on Front	1	Painted	Painted
30702-058	3U	Vopsit Pulbere	Screw-on Front	1	Painted	Painted
30702-046	3U	Anodized	Screw-on Front	1	Raw	Raw
30702-045	2U	Anodized	Screw-on Front	1	Raw	Raw
30702-049	3U	Anodized	Screw-on Front	1	Anodized	Anodized


Table 2/2

Număr de catalog	Treated Edges	Color Code	EMC Shielding	Height (H)	Type	Width (W)
30118-962		RAL 7021	No	43.6mm	19" Front Panel	483mm
30702-047	Yes		No	43.6mm	19" Front Panel	483mm
30702-056		RAL 7035	No	43.6mm	19" Front Panel	483mm
30702-044			No	43.6mm	19" Front Panel	483mm
30118-963		RAL 7021	No	88.1mm	19" Front Panel	483mm
30702-048	Yes		No	88.1mm	19" Front Panel	483mm
30702-057		RAL 7035	No	88.1mm	19" Front Panel	483mm
30118-964		RAL 7021	No	132.5mm	19" Front Panel	483mm
30702-058		RAL 7035	No	132.5mm	19" Front Panel	483mm
30702-046			No	132.5mm	19" Front Panel	483mm
30702-045			No	88.1mm	19" Front Panel	483mm
30702-049	Yes		No	132.5mm	19" Front Panel	483mm

DETALII SUPLIMENTARE DESPRE PRODUS

Please order 19" assembly kit separately.

DIAGRAMS

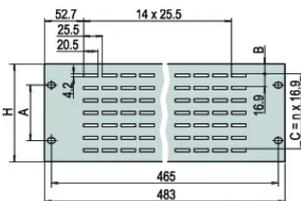

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O

instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE