


AMC Front Panel With Pull Handle

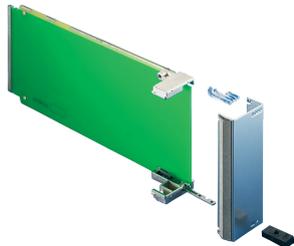

AdvancedMC Front Panel including EMC gasket for AMC.0 Rev. 2.0 Modules.

CERTIFICATIONS



CARACTERISTICI

In accordance with AMC.0 R2.0 specification

Front panel for pull-handle mechanism (with cut-outs for light pipe)

For the use together with the AMC Pull-handle mechanism, AMC.0 R2.0

SPECIFICAȚII

Accessory Type: Front panel

Product Type: Front Panel

Table 1/2


Număr de catalog	Height (H)	Rack Width	Design Feature	Material	Finish	Package Quantity
30849-658	73.8mm	4HP	Mid-Size	Aluminiu	Passivated	1
30849-694	148.8mm	6HP	Full-Size	Aluminiu	Passivated	1
30849-406	148.8mm	4HP	Mid-Size	Stainless Steel		1
30849-402	73.8mm	3HP	Compact	Stainless Steel		1
30849-403	73.8mm	4HP	Mid-Size	Stainless Steel		1

Număr de catalog	Height (H)	Rack Width	Design Feature	Material	Finish	Package Quantity
30849-682	73.8mm	6HP	Full-Size	Aluminiu	Passivated	1
30849-407	148.8mm	6HP	Full-Size	Stainless Steel		1
30849-404	73.8mm	6HP	Full-Size	Stainless Steel		1
30849-670	148.8mm	4HP		Aluminiu	Passivated	1

Table 2/2

Număr de catalog	Front Finish	Rear Finish	Depth (D)	Width (W)
30849-658	Raw	Raw	2.5mm	19mm
30849-694	Raw	Raw	2.5mm	29mm
30849-406	Raw	Raw	1mm	19mm
30849-402	Raw	Raw	1mm	13.9mm
30849-403	Raw	Raw	1mm	19mm
30849-682	Raw	Raw	2.5mm	29mm
30849-407	Raw	Raw	1mm	29mm
30849-404	Raw	Raw	1mm	29mm
30849-670	Raw	Raw	2.5mm	19mm

DIAGRAMS

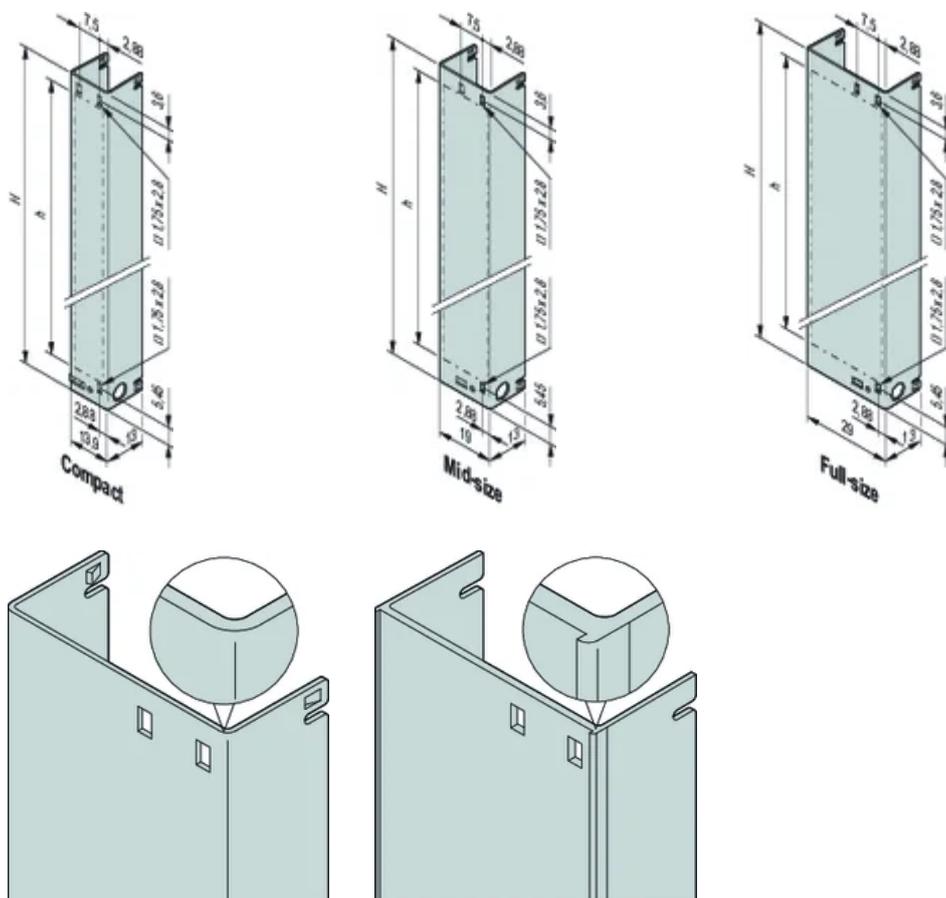

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE