


# Double Test Socket, Ø 2 mm

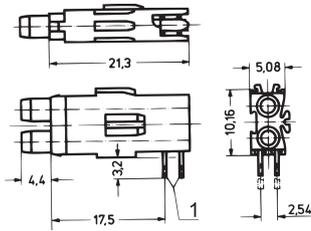

Double test sockets for mounting plane 1 and 2, short and long type.

Solder temperature should only be applied for a maximum of 5 seconds. The plastic body should be protected from the solder wave when wave soldering.

## CERTIFICATIONS



## CARACTERISTICI

Double test sockets for Front Element System

## SPECIFICAȚII

**Diameter:** 2mm  
**Product Type:** Socket

Table 1/2

Număr de catalog	Type	Package Quantity	Voltage AC	Max Current	Test Voltage @ 50 Hz	Ambient Temperature
69004-089	Long, Mounting Plane 1	1	30V	1A	1kV	-25 to 70°C
69004-131	Short, Mounting Plane 1	1	30V	1A	1kV	-25 to 70°C
69004-090	Long, Mounting Plane 2	10	30V	1A	1kV	-25 to 70°C

Table 2/2

Număr de catalog	Solder Temperature	Flammability Rating
69004-089	260°C	UL® 94V-0

Număr de catalog	Solder Temperature	Flammability Rating
69004-131	260°C	UL® 94V-0
69004-090	260°C	UL® 94V-0

## DETALII SUPLIMENTARE DESPRE PRODUS

Dimensions of connecting pins: 0.3 × 0.6 mm.

Required front panel drill hole: Ø 4 mm.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**