


MTCA.0 System for 2 Single Full-Size AMC Modules, 1 HE

NUMĂR DE CATALOG

11850-023

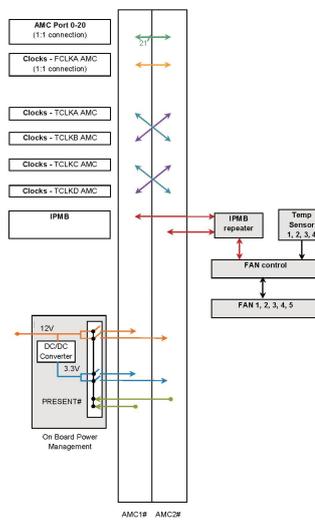

The System is designed for 2 AMC modules. The integrated Power Supply and Power switches on the backplane enable the Payload Power to the AMC Modules without the need for a separate MCH.

CERTIFICATIONS



CARACTERISTICI

Small, compact case to hold 2 single full-size AdvancedMC modules With an optional 2 HP filler module, 2 single mid-size modules can also be fitted

Direct connection of all ports between both AdvancedMC slots (see backplane topology); data transfer rates up to 10 Gbps per port

90 - 264 VAC wide range input on rear of case, 150 W power supply in rear section of enclosure

12 VDC voltage is activated by the AdvancedMC module presence signal

150 W cooling capacity at an ambient temperature of 55 °C, airflow from right to left, temperature-regulated fans

Fan unit and fan filter are easy to service or replace

The enclosure is stackable and prepared for plate mounting

ATRIBUTE PRODUS

Product Type: System

Number of Slots: 2

Type: Pico System

Backplane Type: All Ports Point to Point Connected

Data Transfer: 40 GbE; PCIe Gen3

Power per Slot: 60W

Input Voltage AC: 100 – 240V

Airflow Direction: Right to Left

Rack Height: 1U

Power Supply Type: Open Frame

Power Supply Included: Yes

Rear I/O: No

Complies With: PICMG MTCA.0 R2.0

Depth: 302mm

Package Quantity: 1

DETALII SUPLIMENTARE DESPRE PRODUS

Modified systems available on request.

Completely assembled, wired and tested.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE