


# MTCA.0 System for 6 Single Mid-Size AMC Modules, MTCA.0, 1 U, 84 HP

## NUMĂR DE CATALOG

11850-025

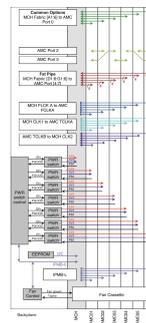

1 U MicroTCA System with horizontal card cage for Single Width AdvancedMC Modules. The chassis has an AC Power input in the rear and an integrated 400 W Power Supply. The PM EMMC (Power Module Enhanced Management Controller) is installed onto the rear of the Backplane.

## CERTIFICATIONS



## CARACTERISTICI

In accordance with PICMG MTCA.0 R1.0 specification

1 U, 19" subrack system for 6 Single Mid-Size AdvancedMC modules, 1 Single Full-Size MCH

AC mains input (100 ... 240 VAC) on rear of case, embedded 400 W PSU, power management (PM EMMC) on backplane

Hot-swap fan module with cooling unit manager (CU EMMC), airflow from right to left

Air filter access from front

## ATRIBUTE PRODUS

Product Type: System

Number of Slots: 6

Type: 19" Rack Mount

Backplane Type: MTCA.0 Star Topology, Scope Proposal

Data Transfer: 40 GbE; PCIe Gen3

Power per Slot: 50W

Input Voltage AC: 100 – 240V

Airflow Direction: Right to Left

Rack Height: 1U

Power Supply Type: Open Frame

Power Supply Included: Yes

Rear I/O: No

Complies With: PICMG MTCA.0 R2.0

Depth: 301mm

Height: 44.45mm

Net Weight: 5.61kg

Package Quantity: 1

## DETALII SUPLIMENTARE DESPRE PRODUS

Modified systems available on request.

Completely assembled, wired and tested.

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**