


Collar Screw, Torx8 / Slotted, M2.5x12.3 mm, Steel Nickel Plated, 100 pcs

NUMĂR DE CATALOG

21101-976

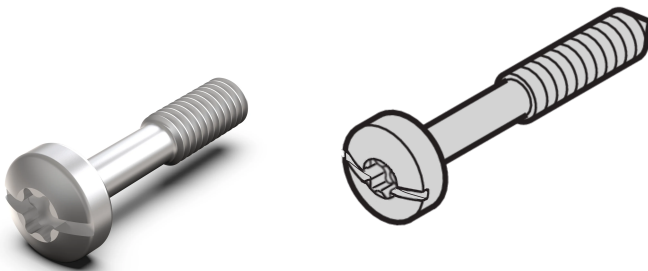

A collar screws enable front panel fixing onto a subrack, case or a system.

CARACTERISTICI

The collar screws enable front panel fixing onto a subrack, case or a system

Collar screw Torx 8 / slotted

ATTRIBUTE PRODUS

Product Type: Screw

Type: Screw

Works With: Front Panels

Package Quantity: 100

Thread Size: M2.5

Length: 12.3mm

Material: Oțel

Finish: Nickel Plated

Net Weight: 0.05kg

Torque: 0.3N·m

DETALII SUPLIMENTARE DESPRE PRODUS

Enable the mounting of front panels when using threaded inserts.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE