
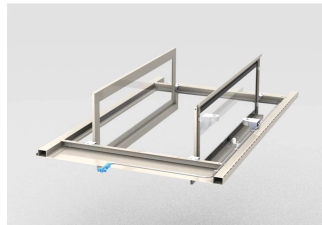


Aisle Containment Automatic Top Cover, 1200W 600D, RAL 7021

NUMĂR DE CATALOG

21130-592

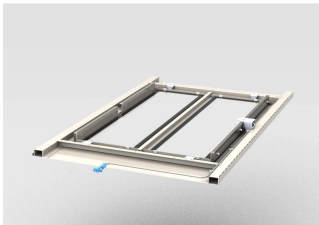

Top cover that can be automatically opened in case of an event on site.

CERTIFICATIONS



CARACTERISTICI

Automatic containment top covers open automatically in the event of fire so that the facility sprinkler systems can put out the fire. In normal operation, the top covers are kept closed by electromagnets and open when the floating contact of the fire detection system is opened

Suitable for an aisle width of 1200 mm

Top cover with safety glass, 7 mm

With the universal top cover profile, the aisle height can be increased by 84 mm; please order separately

The top cover can be removed from the inside. When opened, the top cover provides access to lighting and sprinkler systems above the containment system for maintenance work

Please order the control unit, which can be used to control up to 12 automatic top covers, separately

A 24 VDC power supply unit is required to operate the system. Please order separately

ATTRIBUTE PRODUS

Width: 600mm

Depth: 1200mm

Package Quantity: 1

Color: Black Grey

Color Code: RAL 7021

Finish: Vopsit Pulbere

Material: Oțel; Glass

Product Type: Cover

Type: Aisle Top Cover, Automatic

Works With: Aisle Containment

Net Weight: 31.25kg

DETALII SUPLIMENTARE DESPRE PRODUS

Please order the control unit, which can be used to control up to 12 automatic top covers, separately.

A 24 VDC power supply unit is required to operate the system. Please order separately.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE