
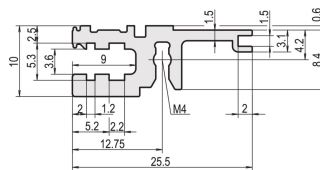


Horizontal Rail, Front, Type L-OD, Light, Without Lip, 28 HP

NUMĂR DE CATALOG

34560-028

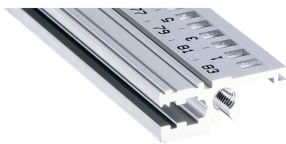

Combinations of horizontal rails and side panels

		"L" can be combined				"H" combination not recommended			
Subrack 28 HP	Subrack 28 HP	-	+	+	+	+	+	+	+
	Subrack 28 HP (with lip)	+	+	+	+	+	+	+	+
Subrack 18 HP	Subrack 18 HP	+	+	-	-	+	+	-	-
	Subrack 18 HP (with lip)	+	+	-	-	+	+	-	-
Subrack 12 HP	Subrack 12 HP	+	+	-	-	+	+	-	-
Subrack 6 HP	Subrack 6 HP	+	+	-	-	+	+	-	-

The horizontal rail without a lip enable the use of a setups such as a 6 U front panel for a subrack which is split into 2 x 3 U.

CERTIFICATIONS



CARACTERISTICI

For installation behind full-width front panel

< 28 HP not to print

Without lip (L-OD)

Aluminum extrusion, anodized finish, conductive contact surface

ATRIBUTE PRODUS

Rack Width: 28HP

Package Quantity: 1

Finish: Anodized

Length: 147.32mm

Material: Aluminiu

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Product Type: Horizontal Rail

Type: Light, OD

Works With: Subracks; Cases

Gross Weight: 0.046kg

DETALII SUPLIMENTARE DESPRE PRODUS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE