


Horizontal Rail Rear, Type AB for Rear I/O, With Notch, 84 HP

NUMĂR DE CATALOG

34579-040

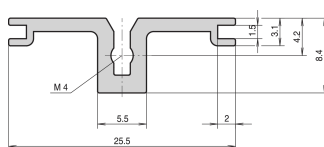

Combinations of horizontal rails and side panels

+ = can be combined,
 - = combination not recommended

Subrack 1 L		-	-	-	-	Subrack 1 R suggested
		-	-	-	-	Subrack 2 L suggested
Subrack 2 L		+	+	+	+	Subrack 2 R suggested
		+	+	+	+	Subrack 1 R suggested
Horizontal rail		+	+	+	+	Horizontal rail Dark
		+	+	+	+	Horizontal rail Light
Side panel		+	+	+	+	Side panel Dark
		+	+	+	+	Side panel Light
		Subrack 1 L	Subrack 1 R	Subrack 2 L	Subrack 2 R	Horizontal rail
		Side panel	Horizontal rail	Subrack 1 L	Subrack 1 R	Subrack 2 L

+ = can be combined,
 - = combination not recommended

Aluminum extrusion horizontal rail of the type AB (AB = support), for rear I/O card guides, with an anodized surface and conductive contact surface. Suitable for RatiopacPRO/-AIR and EuropacPRO/-rugged).

CARACTERISTICI

For CompactPCI in the area of rear I/O

For 2 x 3 U expansion, 2 horizontal rails of type AB are required

Aluminum extrusion, anodized surface, conductive contact surface, without HP markings

ATTRIBUTE PRODUS

Rack Width: 84HP

Package Quantity: 1

Finish: Anodized

Length: 431.8mm

Material: Aluminu

Product Family: EuropacPRO

Product Type: Horizontal Rail

Type: Type AB

Works With: Subracks

Net Weight: 0.073kg

Rail Type: With Notch

DETALII SUPLIMENTARE DESPRE PRODUS

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE