


Socket Strip, SCHUKO/UTE, Local Display, 6 x SCHUKO/UTE Outlets

NUMĂR DE CATALOG

60110-294

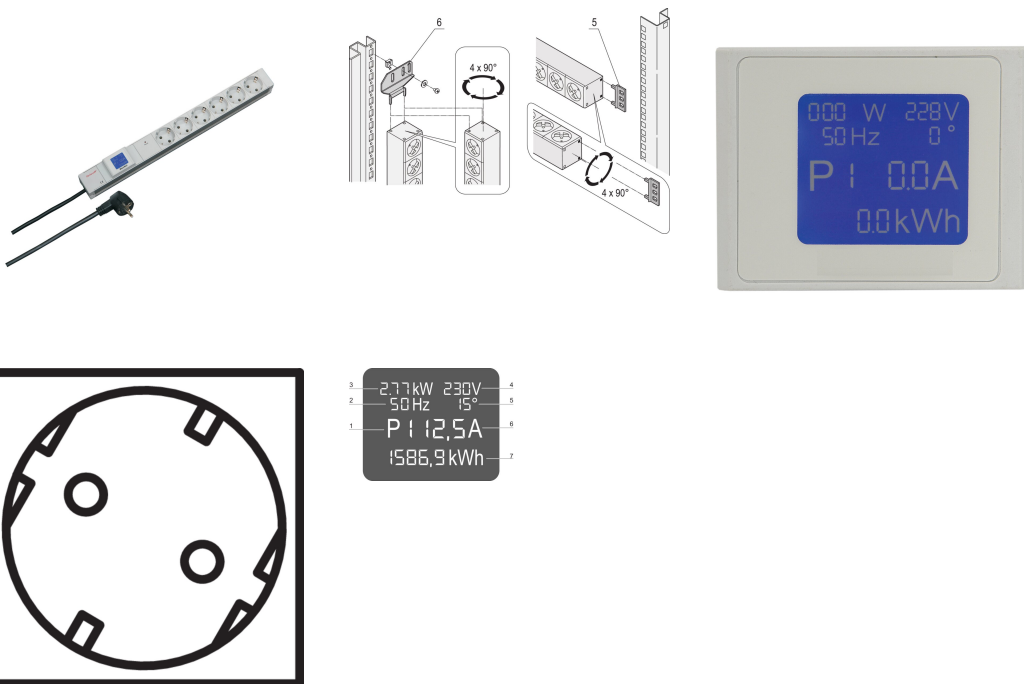

PDU with local power meter. Relevant Power data are shown on an integrated display.

CERTIFICATIONS



CARACTERISTICI

Integrated measurement and display via local display unit

Socket strips with Schuko sockets

Mounting height 1 U

Socket strips can be rotated through all four directions (in 90° increments) during installation

Horizontal and vertical mounting

Measurement functions: Voltage, Current, Power, Frequency, cos phi

ATRIBUTE PRODUS

Product Type: Socket Strip

Socket Type: SCHUKO

Socket Quantity: 6

Color: Grey

Switched Outlets: No

Length: 438.5mm

Voltage AC: 230V

Depth: 44mm

Finish: Anodized

Gross Weight: 0.886kg

Material: Aluminiu; Polyamide

Package Quantity: 1

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE