


Guide Rail Standard Type, With DIN Connector Fixing, Plastic, 220 mm, 2 mm Groove Width, Red, 1 Pair

NUMĂR DE CATALOG

64560-075

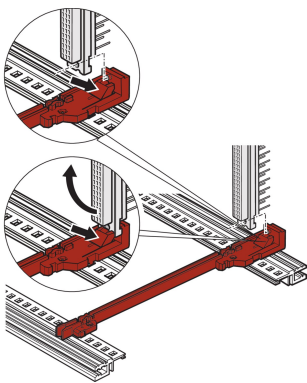

The the standard type guide rail with connector fixing allows the user to clip the DIN connectors (EN 60603-2 (DIN 41612)) directly onto the guide rails. Only applicable with Euroboards with the dimensions 100 x 160 mm and 100 x 220 mm. Suitable for RatiopacPRO/-AIR, PropacPRO, CompacPRO and EuropacPRO.

CERTIFICATIONS



CARACTERISTICI

Easy and economic mounting of connectors through snap connections as alternative to z-rails or horizontal rails with integrated z-rail

For single Euroboard format 100 × 160 mm or 100 × 220 mm; not suitable for double Euroboard format

Plastic guide rail, one piece, red, for 2 mm groove width

Can be clipped into horizontal rails in Al extrusion

Can be clipped into 1.5 mm thick plate

Storage temperature: from -40 °C ... 130 °C

ATRIBUTE PRODUS

Package Quantity: 2

Board Depth: 220mm

Groove Width: 2

Color: Red

Complies With: EN 60603-2 (DIN 41612)

Material: Polybutylene Terephthalate

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac

Product Type: Guide Rail

Type: Standard with DIN Connector

Works With: Subracks; Cases; Chassis

Package Unit: Pair

Net Weight: 0.026kg

DETALII SUPLIMENTARE DESPRE PRODUS

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE