


# Front Panel, Flat, Unshielded, D-Sub Cutouts

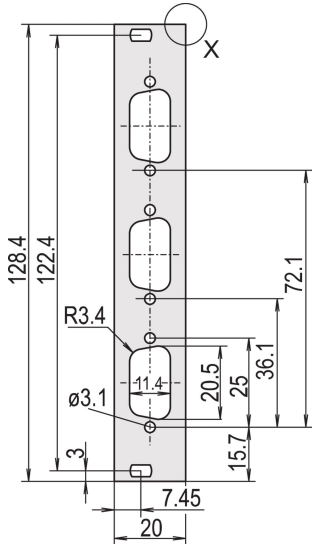

Flat front panel with cutout for D-Sub connectors.  
Unshielded version.

## CERTIFICATIONS



## CARACTERISTICI

Non-shielded version

Al, 2.5 mm, front anodized, rear conductive

## SPECIFICAȚII

<b>Rack Height:</b>	3U
<b>Rack Width:</b>	4HP
<b>Material:</b>	Aluminiu
<b>Finish:</b>	Anodized; Passivated
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel
<b>Type:</b>	Front Panel without Handle

Table 1/2

Număr de catalog	Package Quantity	Mounting	Front Finish	Rear Finish	Number of Pins	Treated Edges
30118-343	1	Screw-on Front	Anodized	Conductive	(1) 25	No
30118-345	1	Screw-on Front	Anodized	Conductive	(2) 15	No
30118-344	1	Screw-on Front	Anodized	Conductive	(2) 9	No
30118-346	1	Screw-on Front	Anodized	Conductive	(2) 25	No
30118-347	1	Screw-on Front	Anodized	Conductive	(3) 9	No
30118-342	1	Screw-on Front	Anodized	Conductive	(1) 15	No
30118-341	1	Screw-on Front	Anodized	Conductive	(3) 9	No

Table 2/2


Număr de catalog	Complies With	Depth (D)	EMC Shielding	Height (H)	Width (W)
30118-343	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm
30118-345	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm
30118-344	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm
30118-346	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm
30118-347	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm
30118-342	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm
30118-341	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	No	128.4mm	19.98mm

## DETALII SUPLIMENTARE DESPRE PRODUS

Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

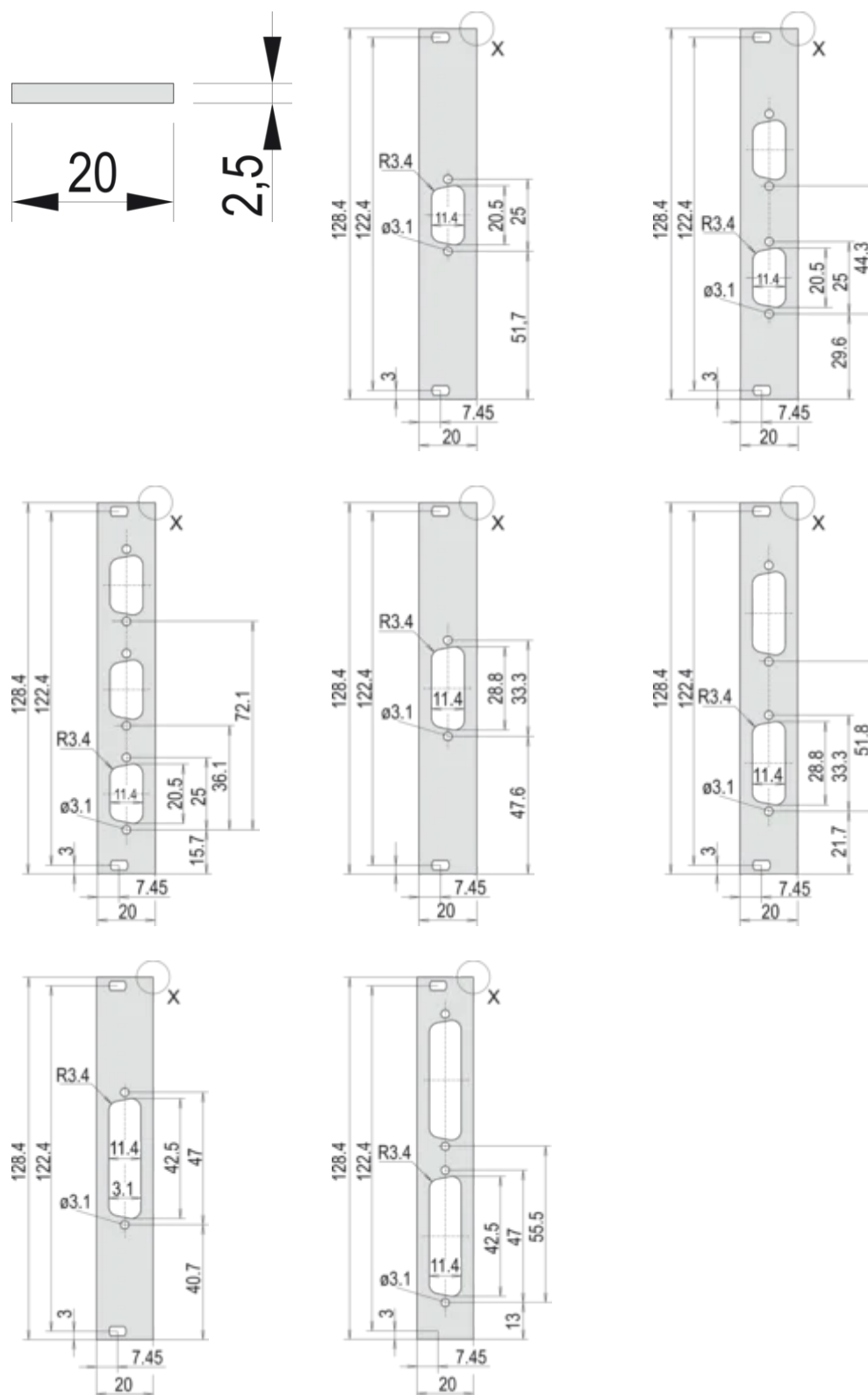

**AVERTIZARE**

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**