


# PropacPRO Rear Panel, Full Width, Unshielded

The rear panel, full width for PropacPRO Case mounts to the frame of the case. With or without vented slots.

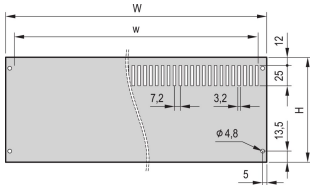

## CERTIFICATIONS



## CARACTERISTICI

Alu panel, 2.0 mm (84 HP 2.5 mm)

Mounting with support bracket on case (right and left)

## SPECIFICAȚII

<b>Material:</b>	Aluminiu
<b>Finish:</b>	Anodized
<b>Works With:</b>	Cases
<b>Product Family:</b>	PropacPRO
<b>Type:</b>	Rear Panel
<b>Product Type:</b>	Side Panel

Table 1/2

Număr de catalog	Rack Height	Rack Width	Design Feature	Package Quantity
24576-153	4U	63HP	Perforated	1
24576-145	2U	63HP	Perforated	1
24576-050	3U	84HP	Non-Perforated	1
24576-149	3U	63HP	Perforated	1
24576-150	3U	84HP	Perforated	1

Număr de catalog	Rack Height	Rack Width	Design Feature	Package Quantity
24576-049	3U	63HP	Non-Perforated	1
24576-052	4U	42HP	Non-Perforated	1
24576-148	3U	42HP	Perforated	1
24576-045	2U	63HP	Non-Perforated	1
24576-152	4U	42HP	Perforated	1
24576-053	4U	63HP	Non-Perforated	1
24576-047	3U	28HP	Non-Perforated	1
24576-054	4U	84HP	Non-Perforated	1
24576-048	3U	42HP	Non-Perforated	1
24576-154	4U	84HP	Perforated	1
24576-146	2U	84HP	Perforated	1
24576-044	2U	42HP	Non-Perforated	1
24576-046	2U	84HP	Non-Perforated	1
24576-158	6U	84HP	Perforated	1
24576-147	3U	28HP	Perforated	1

Table 2/2

Număr de catalog	Rack Height	Rack Width	Design Feature	Package Quantity
24576-058	6U	84HP	Non-Perforated	1
24576-144	2U	42HP	Perforated	1

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**