


# PSU Front Panel

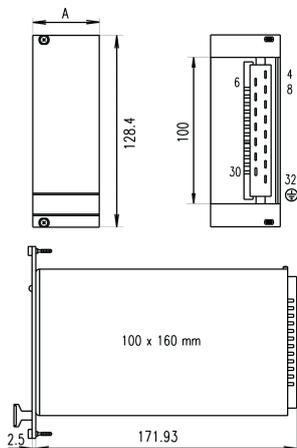

Front Panel for nVent SCHROFF 19" compatible Power Supply. Flat front panel with vertical grooves for stainless steel EMC Contact Strips.

## CERTIFICATIONS



## CARACTERISTICI

Front Panel, Al, Front anodized, rear conductive, with vertical Slots for EMC Contact Strips

## SPECIFICAȚII

**Accessory Type:** Front panel

Table 1/2

Număr de catalog	Material	Front Finish	Rear Finish	Treated Edges	Rack Height	Height
21005-439	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21006-959	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-478	Aluminiu	Anodized	Conductive	No	3U	128.4mm
31006-677	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-477	Aluminiu	Anodized	Conductive	No	3U	128.4mm

Număr de catalog	Material	Front Finish	Rear Finish	Treated Edges	Rack Height	Height
21006-954	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-470	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21006-955	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-476	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21006-945	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21006-956	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-474	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-451	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21006-957	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21006-943	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-475	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-473	Aluminiu	Anodized	Conductive	No	3U	128.4mm

Table 2/2

Număr de catalog	Rack Width	Width	Depth	Package Quantity	Finish
21005-439	14HP	7078mm	2.5mm	1	Anodized
21006-959	3HP	14.9mm	2.5mm	1	Anodized
21005-478	14HP	70.78mm	2.5mm	1	Anodized
31006-677	8HP	40.3mm	2.5mm	1	Anodized
21005-477	10HP	50.46mm	2.5mm	1	Anodized
21006-954	6HP	30.14mm	2.5mm	1	Anodized
21005-470	6HP	30.14mm	2.5mm	1	Anodized
21006-955	6HP	30.14mm	2.5mm	1	Anodized
21005-476	6HP	30.14mm	2.5mm	1	Anodized
21006-945	8HP	40.3mm	2.5mm	1	Anodized
21006-956	6HP	30.14mm	2.5mm	1	Anodized
21005-474	14HP	7078mm	2.5mm	1	Anodized
21005-451	10HP	50.46mm	2.5mm	1	Anodized
21006-957	6HP	30.14mm	2.5mm	1	Anodized
21006-943	6HP	30.14mm	2.5mm	1	Anodized
21005-475	6HP	30.14mm	2.5mm	1	Anodized
21005-473	10HP	50.46mm	2.5mm	1	Anodized

## AVERTIZARE

---

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**