

Sleeves for M2.5



Sleeve guides the collar screw when fastening the front panel.

CERTIFICATIONS



CARACTERISTICI

Sleeve guides the collar screw when fastening the front panel

Sleeve is inserted into the elongated hole of the front panel

SPECIFICAȚII

Works With: Front Panels

Product Type: Sleeve

Table 1/2

Număr de catalog	Material	Finish	Color	Package Quantity	Color Code	Depth (D)
21100-886	Brass	Organic Top Coat		100		4.4mm
21100-662	Stainless Steel			100		4.4mm
21100-660	Brass	Nickel Plated		100		4.4mm
21100-591	Polyamide 6		Jet Black	100	RAL 9005	6.9mm
21100-464	Polyamide 6		Pebble Grey	100	RAL 7032	6.9mm
21100-659	Brass	Nickel Plated		10		

Număr de catalog	Material	Finish	Color	Package Quantity	Color Code	Depth (D)
21100-661	Stainless Steel			10		
21100-885	Brass			10		

Table 2/2


Număr de catalog	Height (H)	Width (W)	Flammability Rating
21100-886	6mm	8mm	
21100-662	6mm	8mm	
21100-660	6mm	8mm	
21100-591	6mm	6.8mm	UL® 94V-2
21100-464	6mm	6.8mm	UL® 94V-2
21100-659			
21100-661			
21100-885			

DETALII SUPLIMENTARE DESPRE PRODUS

Metal sleeves on the partial front panels must be pressed in.

All sleeves can be used for front panel > 2 HP.

DIAGRAMS

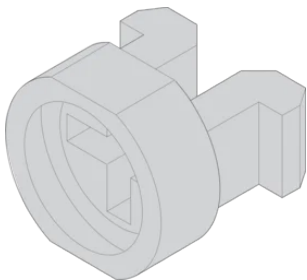

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE