


# Varistar Cable Panel

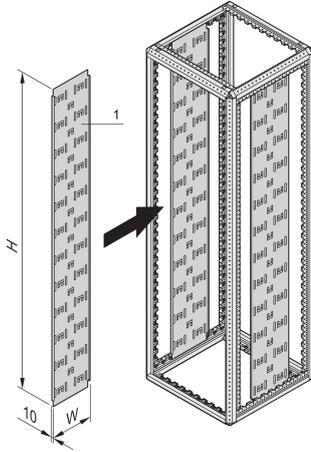

Vertical cable panel for Varistar free standing cabinets powdered in cabinet color in different widths.

## CERTIFICATIONS



## CARACTERISTICI

For fitting directly onto the frame

Cables are assembled in place with cable ties or Velcro

## SPECIFICAȚII

**Product Type:** Cabinet/Rack Panel

**Material:** Oțel

Table 1/2

Număr de catalog	Rack Height	Height	Width	Depth	Package Quantity	Color
23130-625	52U	2450mm	250mm	250mm	2	Black Grey
23130-502		1019mm	110mm	10mm	2	Black Grey
23130-422	47U	2200mm	150mm	150mm	2	Black Grey
23130-501		446mm	110mm	10mm	2	Black Grey

Număr de catalog	Rack Height	Height	Width	Depth	Package Quantity	Color
23130-503		670mm	110mm	10mm	2	Black Grey
23130-500		604mm	110mm	10mm	2	Black Grey
23130-504		496mm	110mm	10mm	2	Black Grey
23130-628	52U	2450mm	150mm	150mm	2	Black Grey
23130-420	38U	1800mm	150mm	150mm	2	Black Grey
23130-150	42U	2000mm	250mm	250mm	2	Black Grey
23130-151	47U	2200mm	250mm	250mm	2	Black Grey
23130-421	42U	2000mm	150mm	150mm	2	Black Grey
23130-499		915.5mm	110mm	10mm	2	Black Grey

Table 2/2

Număr de catalog	Color Code	Finish	Type
23130-625	RAL 7021	Vopsit Pulbere	Cable Panel
23130-502	RAL 7021	Vopsit Pulbere	Cable Panel
23130-422	RAL 7021	Vopsit Pulbere	Cable Panel
23130-501	RAL 7021	Vopsit Pulbere	Cable Panel
23130-503	RAL 7021	Vopsit Pulbere	Cable Panel
23130-500	RAL 7021	Vopsit Pulbere	Cable Panel
23130-504	RAL 7021	Vopsit Pulbere	Cable Panel
23130-628	RAL 7021	Vopsit Pulbere	Cable Panel
23130-420	RAL 7021	Vopsit Pulbere	Cable Panel
23130-150	RAL 7021	Vopsit Pulbere	Cable Panel
23130-151	RAL 7021	Vopsit Pulbere	Cable Panel
23130-421	RAL 7021	Vopsit Pulbere	Cable Panel
23130-499	RAL 7021	Vopsit Pulbere	Cable Panel

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**