



# Cable Entry Systems

Cable Entry Gland Plate Rectangular, CEPH  
(Screw-on mount from the inside.)

Instruction Manual

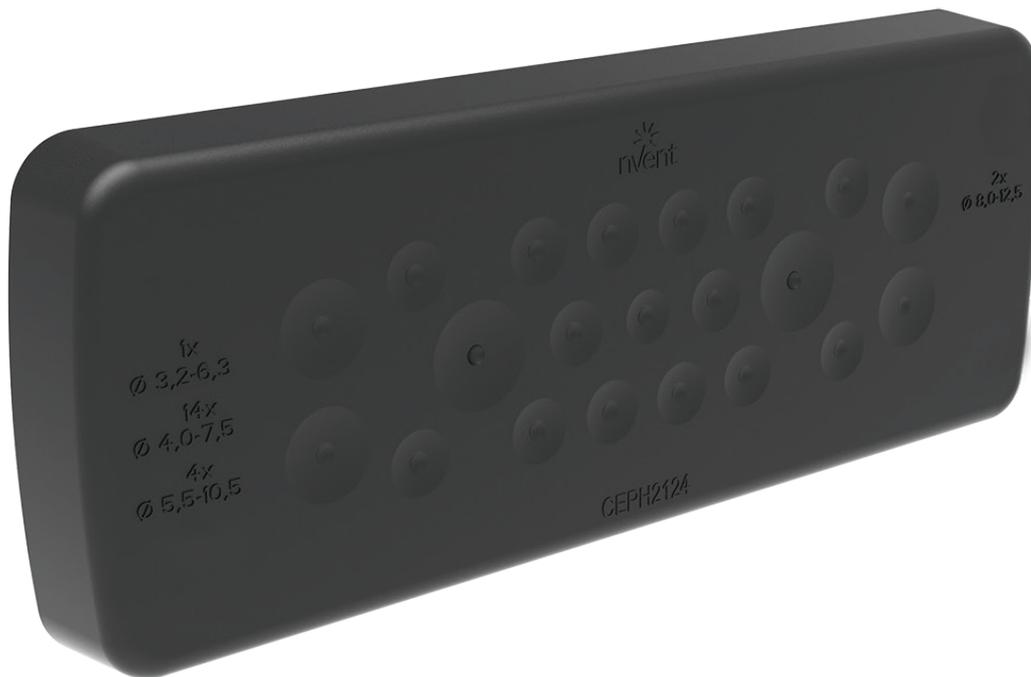

## PRODUCT DATA

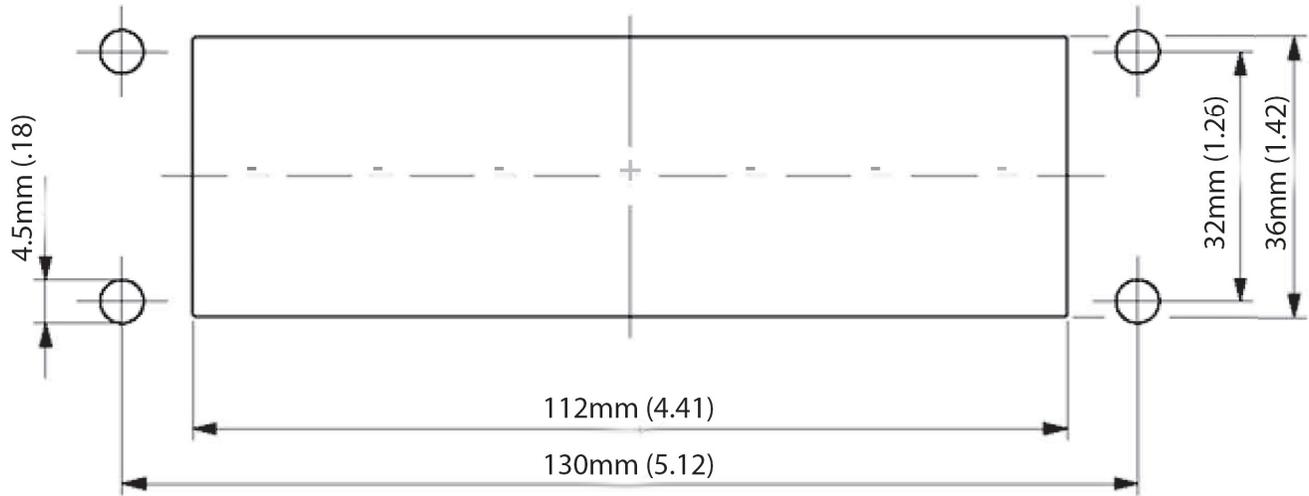

According to UL Standard 508A, the following Conditions of Acceptability apply:

**NEMA Type 4/4X**

Only applies when the CEPH variant is secured with screws and the cables/wires have max. diameter of the pierced membrane holes.



**NEMA Type 1**

When the CEPH variant is secured with screws and fitted with smaller cables/wires.


**NEMA Type 1**

For all CEPH variants secured only by latching clips.


## SCREW-ON MOUNT FROM THE INSIDE – INSTALLATION

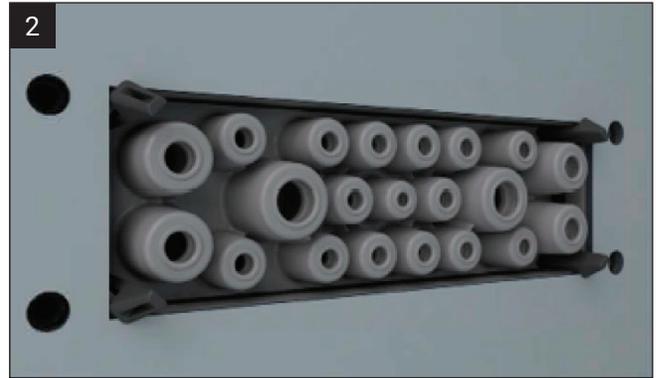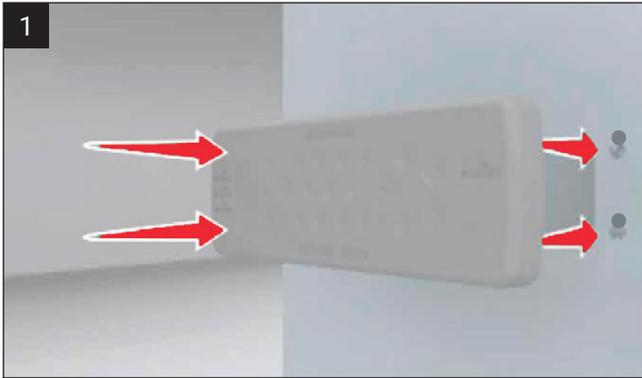


Push through from outside until latching clips click in.

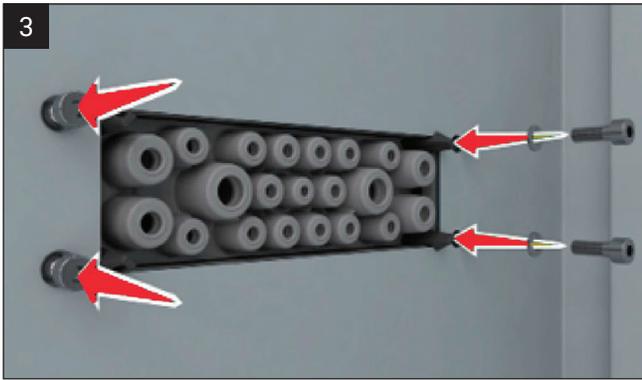

Pierce the membrane at the push-through point.

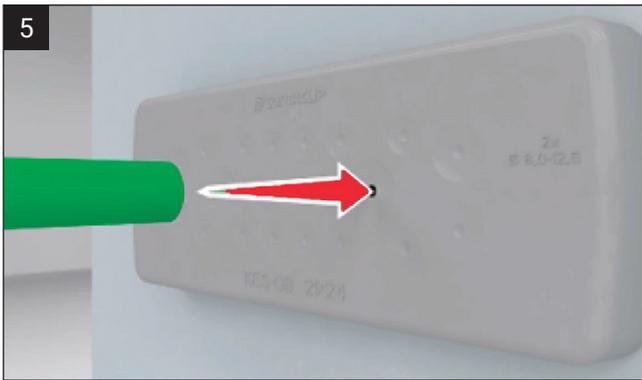

Push through to the inside.

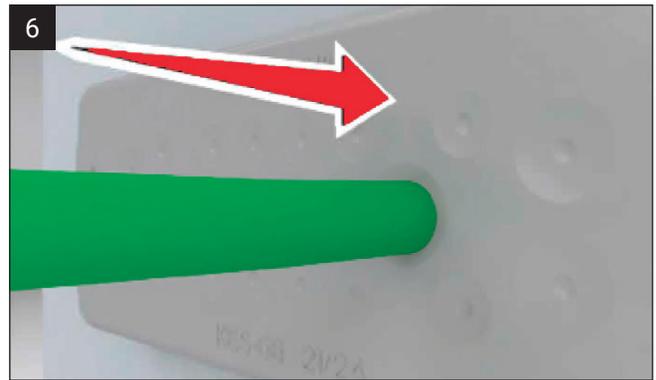



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**