

FleXbus IP55 Conductor Entry, Double Entry, 176 mm x 157 mm x 152 mm

Data Solutions

KATALOGNUMMER

FLEXCEIP55C1002



nVent ERIFLEX FleXbus IP55 Conductor Entries can be used for switchboard and/or power supply cover to upgrade an installation to IP55 level. Protect the nVent ERIFLEX FleXbus Conductor insulation against sharp edges from power supply or switchboard top cover.

CERTIFIERINGAR



DESIGN

Uppfyller RoHS

Made with soft PVC to follow any potential conductor bending radius

Sealing around the conductor is made by a self-fusing tape with a strong adhesive

Good resistance to solvent and hydrocarbon splashes

Adaptable to any nVent ERIFLEX FleXbus conductor cross section by cutting the top material with traditional cutter

High acid resistance

UV resistance

Flame retardant

PRODUKTATTRIBUT

Artikelnummer: 508143

Material: Polyvinylklorid

Kapslingsklass: IP55

Typ: Dubbel genomföring

Arbetstemperatur: -40 to 140°C

A.: 176mm

B.: 157mm


C.: 152mm

Ledarstorlek: 960 mm²; 1280 mm²; 1810 mm²

Vridmoment (TQ): 2.5N·m

Enhetsvikt: 1kg

DIAGRAMS

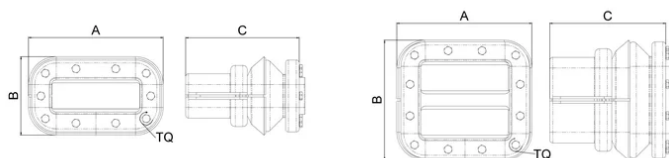

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE