

nVent CADDY Macrofix Insulated M8/M10, 37-44 mm OD, 1 1/4" Pipe, 32 DN

物料号

MFD044



认证



功能

Return-lip on the hanger prevents the rubber from detaching, eliminating rework during installation

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory ☒

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

产品属性

订货号: 586006

材料: 钢;EPDM-SBR 橡胶

完成: 电镀锌

温度: -50 to 110 °C

颜色: 黑色

外径 (OD): 37 - 44 mm

管道尺寸: 1 1/4" Min

NB/DN: 32

杆尺寸 (RS): M8;M10

宽度 (W): 20 mm

厚度 (T): 1 mm

螺钉直径 (Sc): 6


螺钉长度 (L): 27mm

静态负载: 1000N

其他产品详情

Lining is EPDM rubber.

图

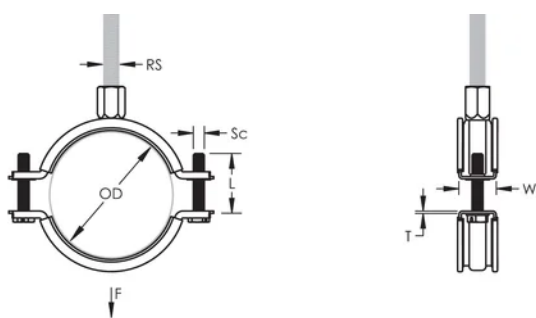

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

