

# nVent CADDY Superfix 243 M8/M10, 74–80 mm OD, 2 1/2" Pipe, 65 DN

## 物料号

**SXD080**



## 认证



## 功能

Includes easy closing mechanism

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## 产品属性

订货号: 400074

材料: 钢;EPDM-SBR 橡胶

完成: 电镀锌

颜色: 黑色

温度: -50 to 110 °C

外径 (OD): 74 - 80 mm

管道尺寸: 2 1/2"

NB/DN: 65

杆尺寸 (RS): M8;M10

宽度 (W): 20 mm

厚度 (T): 2 mm

螺钉直径 (Sc): 6


螺钉长度 (L): 35mm

静态负载: 1300N

## 其他产品详情

Lining is EPDM rubber.

## 图

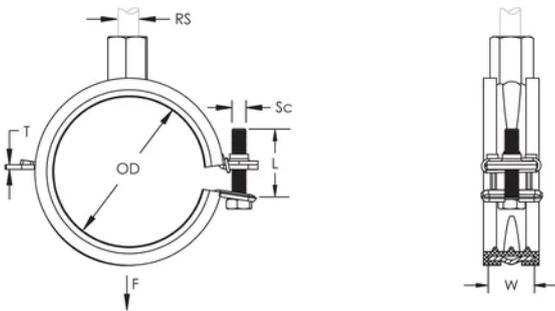

## 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221  
，按 1 转客户服务  
，按 2 转技术支持

欧洲

荷兰：  
+31 800-0200135  
法国：  
+33 800 901 793

欧洲

德国：  
800 1890272  
其他国家/地区：  
+31 13 5835404

亚太地区

上海：  
+ 86 21 2412 1618/19  
悉尼：  
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

