


Comptec GND/Earthing Kit

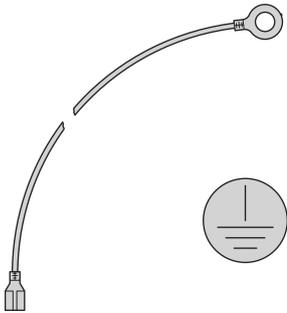

保护性接地连接符合：DIN EN 50178, VDE 0160/DIN EN 62368-1, VDE 0805/DIN EN 61010 - 1, VDE 0411 Part 1/DIN EN 61010 - 1A2, VDE 0411 Part 1/A1.

认证



功能

保护性接地连接符合：DIN EN 50178/VDE 0160/DIN EN 62368-1/VDE 0805/DIN EN 61010 - 1/VDE 0411 Part 1/DIN EN 61010 - 1A2/VDE 0411 Part 1/A1

经过 VDE 测试

技术参数

产品系列: Comptec

类型: 接地套件

产品类型: 接地套件

Table 1/1

物料号	包装数量	搭配
21100-490	1	仪器箱, 钢盖
21100-448	1	仪器箱, 钢盖
21100-347	1	仪器箱, 铝盖

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE