

# 前面板, Front Shielded, 侧面铰链固定

带导电布EMC垫片的面板，侧面铰链固定。



## 认证



## 功能

前面板，带纺织物 EMC 垫片

可安装到水平轨道上

适用于插箱和仪器箱

可在左或右安装铰链

## 技术参数

深度 (D):	2.5mm
机架宽度:	84HP
材料:	铝
完成:	阳极氧化; 钝化
附件类型:	前面板
产品类型:	前面板
类型:	不带把手的前面板
EMC 屏蔽:	无 (可改装)


Table 1/2

物料号	机架高度	包装数量	安装	垫片类型	正面表面处理	反面表面处理
20848-611	3U	1	铰链式，侧面	织物 EMC	阳极氧化	导电
20848-617	6U	1	铰链式，侧面	织物 EMC	阳极氧化	导电

Table 2/2

物料号	边缘处理	高度 (H)	宽度 (W)
20848-611	否	128.4mm	426.4mm
20848-617	否	261.8mm	426.4mm

## 图

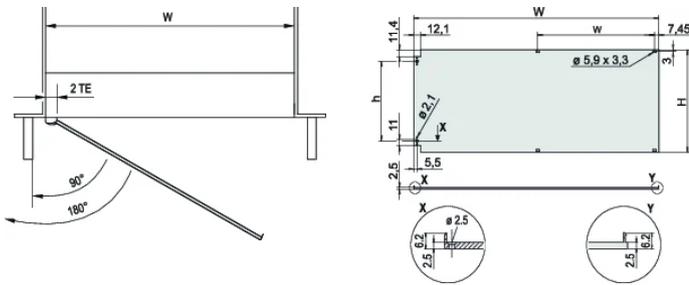

## 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客户经理索取。

## North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](http://nvent.com/schroff)

## Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](http://nvent.com/schroff)

## Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](http://nvent.com/schroff)

## Middle East &amp; India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE