

ATCA Front Panel Kit With Spring Loading



AdvancedTCA

前面板，适用于带压铸尾端件的铝型材或不锈钢材质弹簧支撑IEA把手（柱塞式或杆式）。

认证



功能

前面板（使用压铸端件加固）

ATCA IEA 把手，带弹簧承载装置

EMC 织物垫片和固定材料

技术参数

- 机架宽度: 6HP
- 机架高度: 8U
- 附件类型: 前面板
- 产品类型: 前面板

Table 1/2


物料号	材料	完成	包装数量	正面表面处理	反面表面处理	深度 (D)
20818-160	不锈钢		1	未加工	未加工	1mm
20818-169	铝	钝化	1	未加工	未加工	1mm

物料号	材料	完成	包装数量	正面表面处理	反面表面处理	深度 (D)
20818-161	不锈钢		1	未加工	未加工	1mm
20818-170	铝	钝化	1	未加工	未加工	1mm

Table 2/2

物料号	高度 (H)	宽度 (W)
20818-160	323.15mm	28.95mm
20818-169	323.15mm	28.95mm
20818-161	323.15mm	28.95mm
20818-170	323.15mm	28.95mm

图

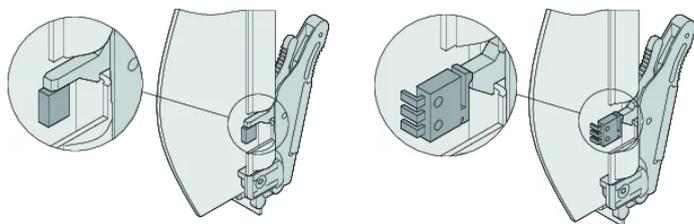

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE